



Wired for Performance; Cable and connectivity solutions



AUTHORIZED DISTRIBUTOR

 nz.rs-online.com



Contents

04 Cables & Heatshrink

05 Cables & Heatshrink

06 Connectors

07 Connectors

Join the conversations



Terms & Conditions

To view our latest prices, charges and full terms see RS Conditions of Sale as set out online at nz.rs-online.com. Prices correct at the time of going to print, prices exclude GST. Published by: RS Components Ltd, Level 6, 56 Cawley Street, Ellerslie Penrose, Auckland.

RS Components Pty Ltd October 2018.
RS are trademarks of RS Components Limited.
An Electrocomponents Company.



AUTHORIZED DISTRIBUTOR



TE Connectivity is a global technology leader offering connectivity solutions that are essential in today's increasingly connected world. As an authorised TE Connectivity global distributor, RS offers competitive pricing and next-day delivery on a huge range of products for standard and MPQ package.

With 24/7 service, plus free tools and 3D models to help you integrate TE products into your designs, we have everything you need to turn your vision into reality.

Need a quote on TE Connectivity products?

There is no need for you to spend time visiting lots of supplier's sites to find the best price for each product. Contact our dedicated Quotation Team with your latest order, and our team will work out where we can find savings for you.

0800 888 780

quotesandtenders@rs-components.com





Trust RS to deliver

We know that improving our performance helps you to improve yours. That's why we're been reviewing our supply chain, upgrading our operations, and streamlining our internal processes to help deliver products faster with more reliability. And you'll enjoy the benefits of these changes every time you order from us.

So now when you see a product on our website, you can be confident it's in our warehouse, ready for shipping. And when you order it, you can trust us to dispatch it the same or next working day.

Work easier and smarter with RS

Finding and ordering the right product is simpler than ever. Our easy-to-use website features thousands of high resolution images and product videos, plus over 100,000 datasheets - helping you quickly find all and buy all the products you need.

And we also offer customized solutions to make your buying process easier and effortless.



nz.rs-online.com

Please note that all prices listed in this brochure are subject to change and may be based on multiple units. Please visit nz.rs-online.com to view the latest prices and for all quantities.

Innovative Solutions

- Providing excellence and **innovation in procurement**
- Providing **asset management** solutions through **smart data**
- Value added **design solutions** driving **customer innovation**



Ease of doing business

Being the easiest place to find and buy products.



Reliability of service

Deliver on time to promise.



Knowledge & expertise

Supported by knowledgeable teams who can help customers across the journey.



Availability & breadth of range

Providing a wide range of products with market leading availability.

100G Series Harsh Environment Wire

- Halogen free, low smoke generation
- Highly flame retardant
- Flexible, easy to install
- Small size, lightweight



244-1380	Blue, 0.5 mm ²	100G0111-0.50-6	Reel of 100 mtrs
244-1453	White, 0.5 mm ²	100G0111-0.50-9	Reel of 100 mtrs
244-1267	Black, 0.75 mm ²	100G0111-0.75-0	Reel of 100 mtrs

1 Pair Screened Multipair Industrial Cable


- Dual wall construction Small size, lightweight
- Low smoke and corrosive gas generation
- Resistant to most chemicals & electrical arc tracking
- Highly flame retardant
- 600 V Voltage Rating



362-594	0.6 mm ² CSA 20 AWG	44A1121-20-0/9-9	Reel of 100 mtrs
362-601	0.6 mm ² CSA 20 AWG	44A1121-20-2/6-9	Reel of 100 mtrs
362-572	0.38 mm ² CSA 22 AWG	44A1121-22-0/9-9	Reel of 100 mtrs
362-588	0.38 mm ² CSA 22 AWG	44A1121-22-2/6-9	Reel of 100 mtrs

Unscreened Flat Ribbon Cable

- A range of IDC flat and flat to round cables directly suitable for IDC connectors
- Parallel stranded tinned copper wire conductors, laminated between layers of blue PVC
- Pitch between conductors 1.27 mm.

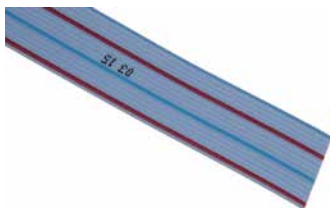

363-654	16 Way, 20.32 mm Width	7-1437356-3	Reel of 30 mtrs
363-711	40 Way, 50.8 mm Width	8-1437357-9	Reel of 30 mtrs
363-660	20 Way, 25.4 mm Width	9-1437356-1	Reel of 30 mtrs

Transparent Solder Sleeves

- These terminals allow earth tags to be created on shielded cables
- Compatible with numerous dielectric and insulating materials, even those that are heat-sensitive
- The solder connections are insulated, protected and highly resistant to mechanical stress due to the combined use of a fluxed solder ring and a heatshrink sleeve



180-8287	0.4 → 1.7mm	CWT3801	Pack of 10
180-8300	1.3 → 2.7mm	CWT3803	Pack of 10
180-8322	1.8 → 4.5mm	CWT3805	Pack of 10
180-8350	3.7 → 8.7mm	CWT3809	Pack of 10

FlexLite Series 100m Polyolefin Equipment Wire

- Flexible with non-melting insulation
- Enables bundles to be routed through areas where conventional wires cannot be used
- UL style 1385
- CSA Class 5851
- Dual wall insulation (Class 2 equipment)



208-5738	Blue, 1 mm ² CSA	FLT0111-1.00-6	Reel of 100 mtrs
208-5788	Black, 1.5 mm ² CSA	FLT0111-1.50-0	Reel of 100 mtrs
208-5801	Blue, 1.5 mm ² CSA	FLT0111-1.50-6	Reel of 100 mtrs
208-5839	White, 1.5 mm ² CSA	FLT0111-1.50-9	Reel of 100 mtrs

HFT5000 Series Black 2:1, Heat Shrink Tubing

- Highly flexible heatshrink woven fabric tubing
- Polyolefin/Polyester construction for excellent abrasion resistance
- 125°C operating temperature (excellent abrasion resistance to 135°C)
- Heat shrinkable to grip substrates tightly without additional fixing



618-9402	20mm Sleeve Dia. x 10m Length	HFT5000-20/10-0	Bag of 10 mtrs
542-3818	30mm Sleeve Dia. x 10m Length	HFT5000-30/15-0	Bag of 10 mtrs
484-8935	40mm Sleeve Dia. x 5m Length	HFT5000-40/20-0-RSU-5M	Bag of 5mtrs
484-8941	50mm Sleeve Dia. x 5m Length	HFT5000-50/25-0	Bag of 5mtrs

Black Polyolefin Adhesive Lined End Caps

- Ensures that cable ends are waterproof and permits long term storage without risk of moisture penetration
- It is a medium wall moulded cap internally coated with an adhesive sealant
- Installation is simple, the cap is centred over the end of the cable and on application of heat the cap shrinks to form a reliable seal



397-657	20mm	KHKB-13359/2	Pack of 5
397-663	35mm	KHKB-13360	Pack of 5

M22759 Single Core Harsh Environment Wire

- Small diameter
- Low smoke and corrosive gas generation
- Chemical resistant and electrical arc tracking
- Cross linked insulation
- Tough physical characteristics



113-5780	3.31 mm ² , 600 V ac, Copper 37 Strands	M22759/32-12-9	Reel of 100 mtrs
113-5781	2.08 mm ² , 600 V ac, Copper 19 Strands	M22759/32-14-9	Reel of 100 mtrs

RPS Series Heat Shrink (Ready to print) Marker

- Ready print markers are designed to meet the wire identification needs of commercial and industrial manufacturers.
- 3:1 shrink ratio
- Flame-retardant
- Resistance against abrasion, aggressive cleaning solvents and industrial fluids



342-7177	White 2.31 → 5.46mm Dia. Range	RPS-1K-16-10/2.0-9	Box of 1000
342-7212	Yellow 1.17 → 2.66 Dia. Range	RPS-1K-22-18/2.0-4	Box of 1000
342-7228	White 1.17 → 2.66 Dia. Range	RPS-1K-22-18/2.0-9	Box of 1000
203-6821	Yellow 1.17 → 2.66mm Dia. Range	RPS-22-18/2.0-4	Box of 250

RW-200 Series Black 2:1, Heat Shrink Tubing

- Premium single wall heatshrink tubing manufactured from a cross-linked fluoroelastomer material
- High resistance to impact and abrasion
- Resistant to a wide variety of fuels, lubricants, acids and solvents to elevated temperatures
- Flexible at low temperatures without cracking



654-4089	12.7mm Sleeve Dia.	RW-200-E-1/2-0	Reel of 6 mtrs
654-4045	3.2mm Sleeve Dia.	RW-200-E-1/8-0	Reel of 10 mtrs
654-4102	25.4mm Sleeve Dia.	RW-200-E-1-0-SP	Reel of 3 mtrs
654-4051	4.8mm Sleeve Dia.	RW-200-E-3/16-0	Reel of 9 mtrs

Expandable Braided Nickel Plated Copper Alloy Cable Sleeve

- Provides EMC screen for wires and cables
- Easy removal from PVC former
- Min. 93%, max. 100% optical coverage
- Highly usable expansion ratio (min 2:1)



887-2844 3mm RAY-103-3.0(10) **Reel of 10 mtrs**

Straight low profile lipped boot

- Ultra low profile construction for utilisation where space is at a premium
- Lipped rim for mounting with backshell adaptor
- Manufactured from fluid resistant elastomer
- Temperature (°C) -75 to +150



360-9284 Size 8/10, 19.3mm 202D921-25-0

TMS-SCE Heat Shrink Cable Marker

- 3:1 Heat-shrinkable polyolefin sleeves
- Flame-retardant
- Resistance against abrasion, aggressive cleaning solvents and military fuels and oils
- Provides insulation and strain relief
- Print is permanent



267-2506	Yellow	TMS-SCE-1/2-2.0-9	Box of 250
267-2578	Brown	TMS-SCE-1/4-2.0-4	Box of 250
267-2433	Gray	TMS-SCE-1/4-2.0-9	Box of 250
267-2556	White	TMS-SCE-1/8-2.0-4	Box of 250

Low Fire Hazard Transparent Solder Sleeves

- An easy single option for connection of wires, soldering, insulation and sealing
- Low fire hazard
- Low temperature



916-2813	2.8 → 7.3mm	B-150-07-S	Box of 100
916-2797	4 → 11.5mm	B-150-11	Box of 100
916-2794	8 → 18mm	B-150-17	Box of 40

CPC BackShell Sealing Boot

- For use with TE Connectivity Circular Plastic Connectors



680-6841 28.58mm max Bundle dia. 207774-3

202A1 Series Black Straight Cable Boot

- Lipless heatshrink boot allows direct mounting to the back of the connector
- Manufactured from fluid resistant elastomer
- Temperature Rating (°C) -75 to +150



170-1338 28.4mm 202A132-3-0

Straight cable boots

- Suitable for long term fluid exposure at elevated temperatures
- Manufactured from fluid resistant elastomer



333-6330	Lipless boot, Size 6, 25.4mm Length	202A111-25-0
333-6346	Lipless boot, Size 8, 38.1mm Length	202A121-25-0
239-1409	Lipped boot, Shell size 12/14, 31mm	202K142-25-0
239-1443	Lipped boot, Shell size 28, 60mm	202K174-25-0

50Ω Cable Mount SMA Connectors

- Subminiature space saving design
- Excellent electrical performance from DC to 18 GHz
- Threaded vibration proof coupling mechanism
- Choice of platings dependent on application



468-3047	Straight, RG405	1-1478904-0
468-3126	Straight, RG17+ A/U, RG188 A/U, RG316/U	1-1478908-0
468-3182	Right Angle, RG17+ A/U, RG188 A/U, RG316/U	1-1478912-0
468-3160	Right Angle, RG141 A/U, RG58 C/U	1-1478923-0

Deutsch 0462 Series Female Crimp Contacts

- For use with DT Series Connector



724-2456 Size 4 100A, Wire size 6 AWG 0462-203-04141

724-2447 Size 8 60A, Wire size 10 → 8 AWG 0462-203-08141

PRO-CRIMPER III SDE Hand Crimp Tool

- High carbon-steel construction for durability
- Ratchet control ensures that a full crimp cycle is achieved
- Standard Die Envelope (SDE) for flexibility and cost savings
- Contact locator, support and wire stops



782-1104 Universal MATE-N-LOK

90546-1

AMP-LATCH Novo Series Wire-To-Board Connector

- 14-way 2-row Vertical Receptacle with tin-plated phosphor bronze contacts and IDC termination
- This AMP-LATCH Novo series low profile connector comes with black thermoplastic housing, accepts 28 to 26AWG ribbon cable



454-2378 2.54mm Pitch

1658621-2

Deutsch DT15 Series Straight Panel Mount PCB Header Connectors

- Environmentally sealed connector
- Rugged thermoplastic connector housing
- Operating temp range -55 to +125 °C
- Moulded in solid copper alloy contacts



724-2529 5.46mm Pitch, 2 Way, 1 Row DT15-2P

724-2532 4.44mm Pitch, 4 Way, 2 Row DT15-4P

724-2539 4.44mm Pitch, 6 Way, 2 Row DT15-6P

724-2541 5.46mm Pitch, 8 Way, 2 Row DT15-8P

AMPLIMITE HD-20 Series Through Hole PCB D-sub Connector Socket

- Straight connectors for PCB mounting
- Boardlocks included as standard
- UL approved
- Gold (Au) plated contacts 0.38µm



480-3910 25 Way 2.77mm Pitch 1-1634224-2 **Pack of 5**

CPC Series Plug & Socket

- Two-Piece sealed circular plastic connector has AMP POWERBAND precision formed power contacts and contains wire entry, peripheral and full interfacial seals



360-2255 16 Pole, Fixed, Panel Mount Plug 206036-4

360-2283 4 Pole, Free, Cable Mount Socket 206153-2

Deutsch IMC Series Industrial Connectors

- For Use With Male to Female Contacts, IP67
- Available in cable plug and panel socket standard mating configuration, cable sockets may also be used to make in-line connections to the cable plug



314-6604 2 Pole, Cable Mount Housing Plug IMC16-2002X

314-6777 7 Pole Cable Mount Housing Socket IMC21-2007X

314-6828 7 Pole Panel Mount Housing Socket IMC24-2007X

314-6711 5 Pole Cable Mount Housing Plug IMC26-2005X

50Ω RF Coaxial Cable Assembly

- RG58 RF/Coaxial Cable Assembly with N type straight plugs, nickel-plated body and gold-plated center contact



409-7698 500mm Length

1337801-2

4PDT PCB Mount Non-Latching Relay

- Miniature plug-in relays
- Sockets available separately
- Applications - telecom, test & measurement equipment
- Contact Material: Ag + Au Sputtered



268-4414 24V dc Coil, 2 A

V23154D 421B110
3-1393807-7

RITS Straight Cable Mount Connector Plug

- Standard interface connector for sensors
- High density 2.0 mm pitch
- Locking lever for secure connection to wire
- Audible click for mating assurance



613-2692 4 Way 2mm Pitch Blue 2-1473562-4

DR Series Miniature Rotary DIP Switches

- 16-position hexadecimal (0-9, A-F) output or 10-position BCD output
- Straight or right angle styles available
- Case material: Polyester
- Shaft: Ø3.2mm; Length: 19mm



256-250 20 mA, Through Hole 4-1825033-1

FASTON series quick connect Crimp Terminals


- Quick application to conductor with use of correct tooling
- Precisely controlled crimping specifications for uniform reliability
- Stable electrical and mechanical performance



246-6575 AWG 18 → 14, Tab crimp 60006-2 **Pack of 100**
719-6928 AWG 20 → 16, Receptacle 60196-2 **Pack of 100**

PIDG Series Insulated Crimp Spade Connectors

- High conductivity copper body
- Copper sleeve for improved wire insulation support
- Serrations in wire barrel for maximum contact and tensile strength
- Colour coded sleeves for easy wire size and tooling identification

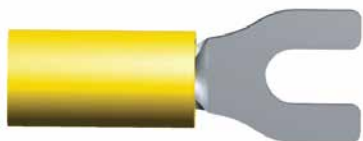

457-5069 Yellow, AWG 12-10, M4 32588 **Pack of 100**
457-5003 Red, AWG 22-16, M3.5 34080 **Pack of 100**

Greenpar Series Coaxial PCB Socket Connectors

- PCB-mount BNC Jack with gold-plated phosphor bronze contacts, polymethylpentene dielectric and nickel-plated zinc body
- The standard RF connector with bayonet locking coupling mechanism and solder termination



512-1477 Straight 5-1634503-1
616-3084 Right Angle 5-1634556-0

Premium Grade TETRA-CRIMP Hand Crimping Tool Frame

- High specification design using high-quality material
- Minimum operator skill required
- CERTI-CRIMP ratchet mechanism guarantees full crimp cycle
- Locator for accurate positioning of the contact



245-5351 26 → 14 AWG 58078-3

Econoseal III 070 Series Headers

- 5mm Pitch, 36 Way, 3 Row, Right Angle PCB Header, Through Hole



679-7110 36 way 344108-1

ERGOGRIMP Series Crimp Die Set

- SDE die assemblies for use with ERGOGRIMP crimping tool and other commercial grade SDE (Standard Die Envelope) hand crimping tools
- These die assemblies are precision designed and manufactured and available for use with a variety of crimp terminal types



452-6679 24 → 12 AWG 539668-2

PIDG FASTON Insulated Crimp Receptacle Terminal

- High conductivity copper body
- Copper sleeve for improved wire insulation support
- Serrations in wire barrel for maximum contact and tensile strength



718-7738 Blue, 16 → 14 AWG 9-160463-5 **Pack of 10**
745-4791 Blue, 17 → 13 AWG 9-160477-2 **Pack of 10**
680-5999 Red, 22 → 15 AWG 9-160583-2 **Pack of 50**
680-5993 Red, 22 → 15 AWG 9-160583-5 **Pack of 100**

A close-up photograph of a woman with dark hair, smiling and wearing a headset with a microphone. She is looking slightly to the right. In the background, another woman is visible, looking towards the camera with a neutral expression. The image is partially obscured by a white text box on the left and a red and purple diagonal graphic at the bottom.

Need a Quote?

You'll get great savings every time with our Quotation Service.

Contact us to see how much you could save:

0800 888 780

quotesandtenders@rs-components.com



nz.rs-online.com

